

Cōncentrate

Let's connect.

Weidmüller 

PRODUCT STORIES

Klippon® Connect – A-series Faster wiring with PUSH IN technology

Weidmüller's A-Series PUSH-IN terminal range offers so much flexibility and functionality. Installation is up to 50% faster with the 'push-in' connection system. Even stranded wire conductors can be connected by simply pressing the pusher without the need for any special tools. The conductor is simply inserted into the contact point as far as the stop and that's it – you have a safe, gas-tight connection. Simply pressing the pusher causes the contact to open and the conductor can be removed – and there's no need for any special tools.

Our spring-loaded mounting foot compensates for differences in terminal rail dimensions. This makes latching and unlatching the terminal blocks easier and speeds up any modifications or rewiring. The new marker strips ensure


effective labelling. They can be created very quickly and attached as strips.

Integrated cross-connection channels increase flexibility and shorten wiring times. All cross-connectors can be adapted and identified easily. A-Series PUSH-IN terminals have a standardised test point that will allow a standard 2 mm multimeter probe to be held captive for measurements that require the test leads to be left in place for a longer time.

Dedicated test plugs are also available and can be stacked together to achieve any desired testing arrangement. Our PUSH-IN design gives these terminals a gas-tight connection with a very high level of shock and vibration resistance, enabling them to be used in the most arduous of applications. Let's connect.

Features

- Standardized test point
- Vibration-resistant, gas-tight connection with copper power rails and stainless-steel spring
- Integrated pushers
- Compensating mounting foot
- Efficient markers
- Integrated cross-connectors

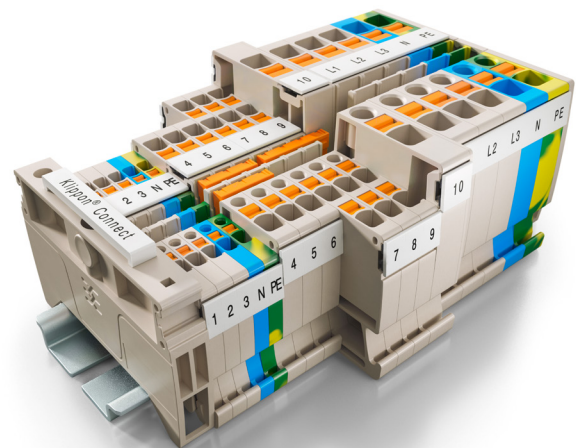

FEATURED PRODUCTS



stripax®

Automatic Stripper & Cutter

- For flexible cables from 0.08mm² to 10mm²
- Self-adjusting blades won't damage cable
- Stripping length up to 25mm adjustable by wire stop
- Removable handle for different size hands & ergonomics

Order number: 9005000000

RRP **\$129.21** EA + GST



KT 45 R

Minimal hand force up to 45mm diameter

- Precisely cuts data, telephone & control cable
- Release option in every cutting position
- Tough Weidmüller ergonomic handle
- Easy one hand ratchet operation

Order number: 9202040000

RRP **\$504.98** EA + GST



PZ 6 Roto L

Professional Crimper

- For ferrules with or without plastic collars
- For cable sizes 0.14 to 6mm² in 1 crimp die
- Ratchet with automatic releaser
- Rotating crimp die now with safety locking mechanism

Order number: 1444050000

RRP **\$305.32** EA + GST



VT & VT M Portable Testers

Non-contact magnetic field or voltage testing

- Visual indication & powerful LED torch included
- Approved to Australian Standard Cat IV/1000V, AS 61010-1
- VT - voltage tester for sensing 120 to 1000Vac
- VT M - magnetic field tester has a self-test via permanent magnet

Ordering data

Type	Description	RRP	Order number
VT	Voltage Tester	\$28.86 + GST	2436660000
VT M	Magnetic Field Tester	\$38.89 + GST	2436680000

TECH TIP

Tech Tip: PRO INSTA power supplies

A lot of small distribution boards, meter cabinets and electrical distributions are often used in the industry. The new PRO INSTA power supplies are a compact, efficient and reliable solution suitable for a variety of applications, including telecommunication and automation systems supporting power requirements up to 96 W. Let's connect.

For more info: www.weidmuller.com.au



Please contact your local authorised distributor for more information
www.weidmuller.com.au/au/distributors

