

Cōncentrate

Let's connect.

Weidmüller 

PRODUCT STORIES

u-remote

Ideal for a faster set-up

Weidmüller's compact distributed I/O platform 'u-remote' delivers the most streamlined design on the market while providing unmatched features such as hot-swappable slices, an integrated self-configuring web server interface and simple plug-in connections.

The u-remote platform is an advanced solution that's built to ensure faster installation and set-up and designed to improve performance and productivity. At only 11.5 mm wide per modular slice, its slim design and high-channel density makes it one of the most feature-rich distributed I/O platforms available.

Being vendor-neutral, it supports integration with all major fieldbus networks including EtherNet/IP, PROFINET, EtherCAT, Modbus TCP, and many more for seamless compatibility with existing plant/machine networks.

An integrated web server helps speed up installation and provides real-time diagnostic access to up to 64 I/O slices/cards connected. Its high-speed system bus also provides impressive electronic performance and works with as many as 256 DI/DOs in just 20 μ s cycle time. Let's connect.

Features

- Vendor-neutral support for all major fieldbuses
- Compact design high density
- Wide range of I/O modules for all applications
- Easy to use webserver for setup and diagnostics



FEATURED PRODUCTS



SCISSOR 2K

Electrician shears and scissors

- The Scissor 2K weighing only 110 grams and 150mm in length are professional electrician shears which are light and easy to use
- Scissor with a wire cutter and serrated cutting blades

Order number: 9918230000

RRP \$26.52 EA + GST



stripax® plus 2.5

Cut, strip & crimp in one tool

- Ergonomically designed
- Strips of ferrules for 0.5 to 2.5mm² cables
- Easy loading of ferrules in strips located in the handle
- Ideal for service and repair

Order number: 902000000

RRP \$401.21 EA + GST



Slimline SoftFinish® Insulated 6 Pcs Screwdriver Set

Long lasting highest quality for the professional

- All screwdrivers are individually tested to 1000VAC
- Fully hardened high alloy, chromium-vanadium-molybdenum steel blade for ultimate service life
- 4 x Slot Head - 3.5 to 6.5mm flat blade
- 2 x Phillips Head – Size 1 & 2

Order number: 1274750000

RRP \$87.79 EA + GST



Field attachable RJ45 connectors

Angled and straight version for optimum cable arrangement

- Up to 10 Gbit/s speed
- Angled adaptors can be rotated through 90°
- Robust die-cast zinc housing
- Dust cap included

Ordering data


Type	Description	RRP	Order number
IE-PS-RJ45-FH-90-A-1.6	Angled	\$31.24 + GST	1992870000
IE-PS-RJ45-FH-180-A-1.6	Straight	\$24.80 + GST	1992820000

TECH TIP

Tech Tip: Terminate Ethernet cables quickly

Weidmüller's range of CAT6a compliant RJ45 connector introduces two new tool-free straight and angled models. Assembly is as simple as arranging the wires into the colour-coded position and snap locking the two sections down – no crimp tool is needed! This allows the plugs to be quickly and simply assembled in the field with an impressive speed of around one minute. Let's connect.

For more info: www.weidmuller.com.au

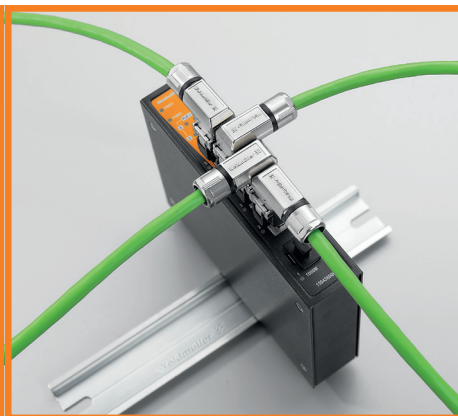

Please contact your local authorised distributor for more information www.weidmuller.com.au/au/distributors

