


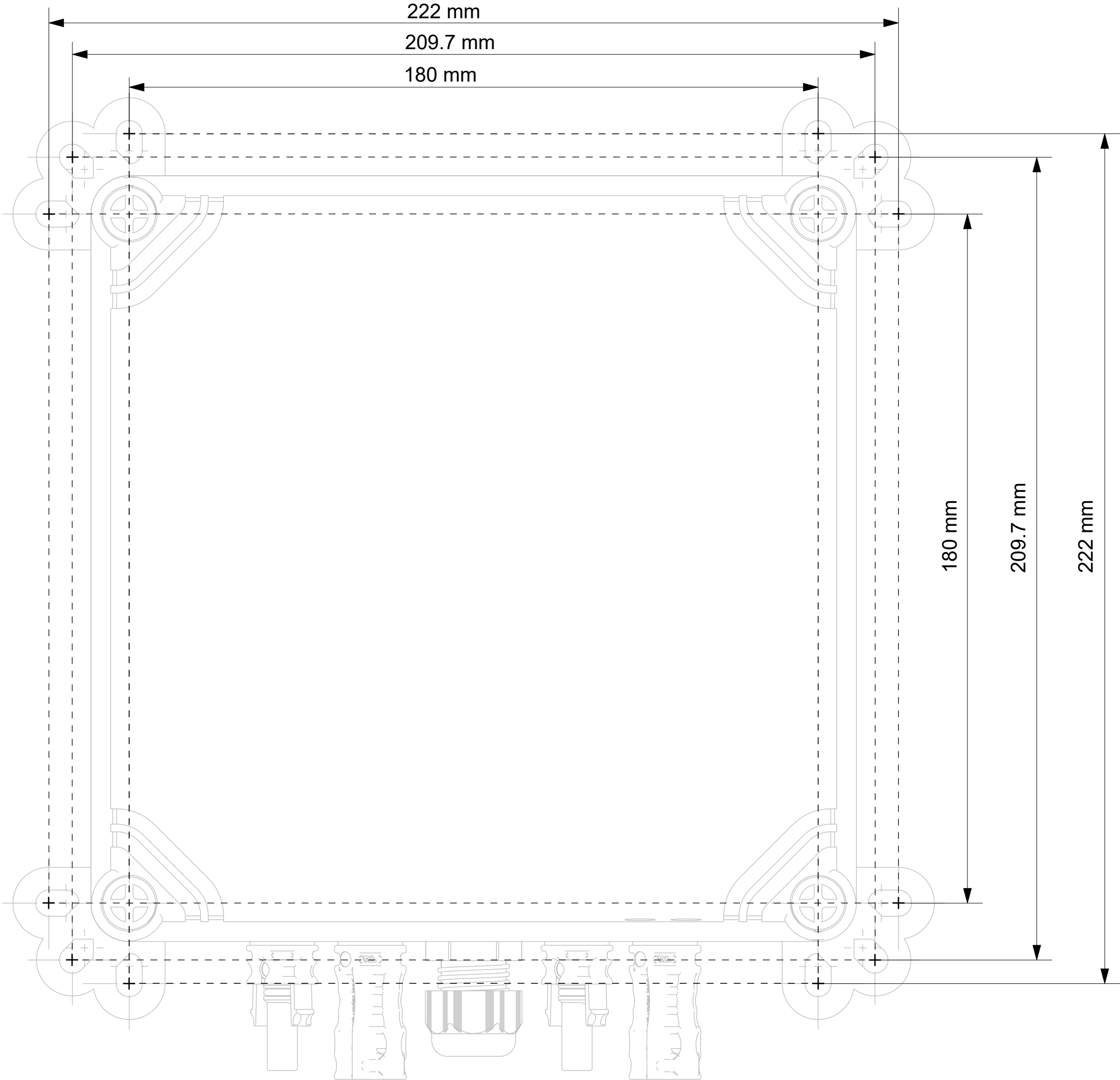

de Bohrschablone
Überspannungsschutzgerät
PV Next

en Drill template
Surge protection device
PV Next

PVN1M1I2SXFV1O1TXPX11	2791920000
PVN1M1I2SXFV1O0TXPX11	2791930000
PVN1M1I2SXFV1O2TXPX11	2866300000
PVN1M1I2SXFV1O0TXPX11	2791930000
PVN1M1I2SXFV2O1TXPX11	2791940000
PVN1M1I2SXFV2O2TXPX11	2866310000
PVN DC 2IN/1OUTX2 2MPPT SPD1R CG 1.1KV	2866320000
PVN DC 2IN/1OUTX2 2MPPT SPD1R WM4C 1.1KV	2866340000
PVN DC 2IN/1OUTX2 2MPPT SPD1R EVO 1.1KV	2866360000
PVN DC 2IN/1OUTX2 2MPPT SPD2R CG 1.1KV	2866330000
PVN DC 2IN/1OUTX2 2MPPT SPD2R WM4C 1.1KV	2866350000
PVN DC 2IN/1OUTX2 2MPPT SPD2R EVO 1.1KV	2866370000
PVN DC 3I 3O 1MPP SPD1R EVO 11	2890320000
PVN DC 3I 3O 1MPP SPD1R WM4 11	2890440000
PVN DC 3I 3O 1MPP SPD1R CG 11	2890560000
PVN DC 3I 3O 1MPP SPD2R EVO 11	2890380000
PVN DC 3I 3O 1MPP SPD2R WM4 11	2890500000
PVN DC 3I 3O 1MPP SPD2R CG 11	2890620000
PVN DC 3I 3O 1MPP SW SPD1R EVO 11	2890350000
PVN DC 3I 3O 1MPP SW SPD1R WM4 11	2890470000
PVN DC 3I 3O 1MPP SW SPD1R CG 11	2890590000
PVN DC 3I 3O 1MPP SW SPD2R EVO 11	2890410000
PVN DC 3I 3O 1MPP SW SPD2R WM4 11	2890530000
PVN DC 3I 3O 1MPP SW SPD2R CG 11	2890650000

de DEUTSCH

 
Deaktivieren Sie die Skalierung beim Druck.
Kontrollieren Sie den Maßstab.

10 mm

en ENGLISH

Deactivate scaling when printing.
Check the scale.

10 mm

 DIN EN ISO 4017
4 x M6 x 30