
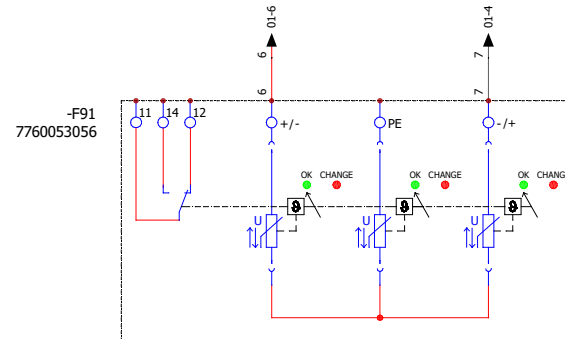
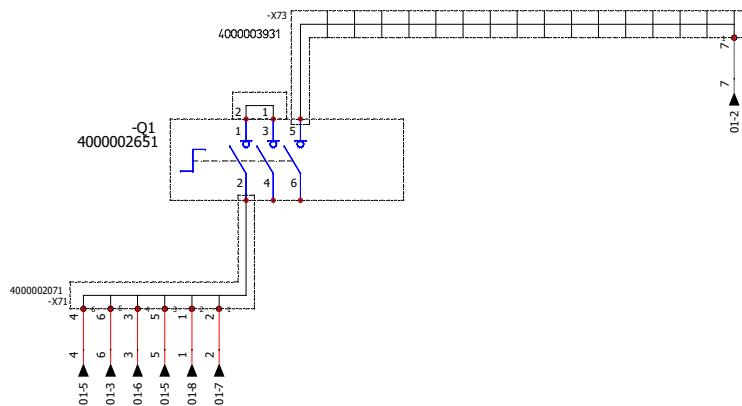
 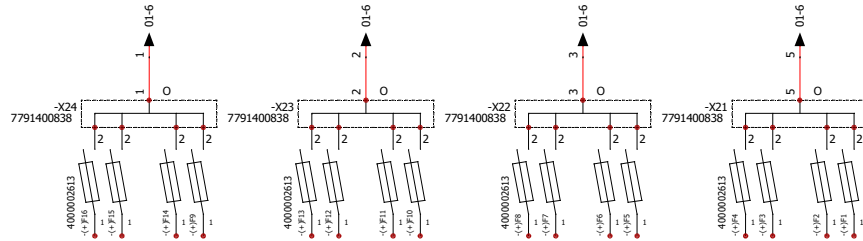


|   |   |   |   |   |   |
|---|---|---|---|---|---|
| A | B | C | D | E | F |
|---|---|---|---|---|---|



|                              |                   |            |         |                                       |                       |                                                                                                               |                                                                                       |                |                |
|------------------------------|-------------------|------------|---------|---------------------------------------|-----------------------|---------------------------------------------------------------------------------------------------------------|---------------------------------------------------------------------------------------|----------------|----------------|
| Additional product documents |                   |            |         | 1.                                    |                       |  Tolerances: ISO 2768-mK |                                                                                       |                |                |
|                              |                   |            |         | 2.                                    |                       |                                                                                                               |                                                                                       |                |                |
|                              |                   |            |         | Drawn                                 | Date<br>31/05/2021    | Name<br>wes0212                                                                                               |  |                |                |
|                              |                   |            |         | Checked                               | 03/06/2021            | wes0212                                                                                                       |                                                                                       |                |                |
|                              |                   |            |         | Criterion for print                   |                       |                                                                                                               | Description:                                                                          |                |                |
|                              |                   |            |         | 1 : 1                                 |                       | A3                                                                                                            | PV 220S0F4CXXV000TXPX15PWW                                                            |                |                |
|                              |                   |            |         | Customer:<br>WEIDMÜLLER INTERFACE GMB |                       |                                                                                                               |                                                                                       |                |                |
| 0                            |                   | 31/05/2021 | wes0212 | Customer-No:<br>104000849             |                       |                                                                                                               | Drawing-No / Material-No:<br><br>8000078883                                           | drw Index<br>0 | Sheet<br>1 / 2 |
| Index                        | Brief Description |            | Date    | Name                                  | Customer Description: |                                                                                                               |                                                                                       |                |                |