




Integrate Your Data Communication in a Remote I/O System Network

Innovative solutions from IP20 to IP67 with RJ45 cables and connectors

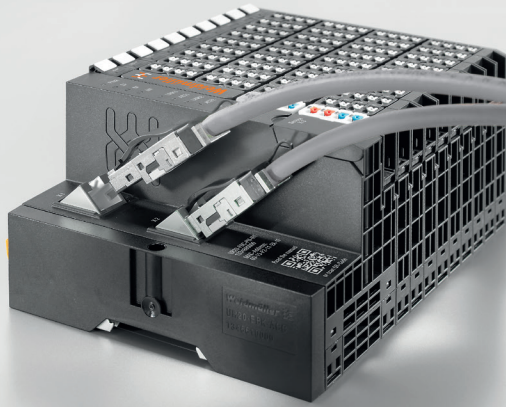

Reduce your cabling workload with our ready-to-connect solutions

- Complete range of high quality RJ45 modular plug based products for all your Industrial Ethernet connectivity needs
- Field attachable RJ45 modular plugs are tool-free, simple to attach, and easy to assemble
- Flexible outlet directions (straight or angled — 90° or 270°) to optimize your cable routing
- DIN rail mounted adapters simplify control cabinet assembly and takes the strain off of sensitive electronic components
- Find the right connection: CabinetLine industrial grade shielded LSZH patch cords are available in 0.2 to 25m lengths and over eight different colors



u-remote: 15 fieldbus couplers + over 80 modules = endless possibilities

- Weidmüller's u-remote is the industry's leading compact, flexible I/O system
- Keep your system up and running with swappable capabilities and visual cues to troubleshoot individual slices
- u-remote adapts to any application and virtually any PLC — giving you ultimate flexibility
- Supports all common fieldbuses and all protocols
- With competitive pricing, fast delivery and ease of use, u-remote is the easy way to future-proof your IIoT network



Seamless connection



High-quality technologies



Flexible customization

Weidmüller, Inc

821 Southlake Blvd.
Richmond, Virginia 23236
Telephone: (800) 849-9343
Website: www.weidmuller.com
Email: customerservice@weidmuller.com

Discover a Wide Range of Accessories for Your u-remote System

Ideal additions to make your applications even more efficient and flexible

Connecting Plug and USB Cable

Type	Order Number
 UR20-PG0.35 connecting plug	1469340000
 IE-USB-A-MICRO-1.8M USB cable, USB A, USB Micro, PVC, 1.8 m	1487980000

DIN Rail Mounting Outlet

Type	Order Number
 Mounting rail outlet, RJ45, coupling, IP20, Cat.6A / Class EA (ISO/IEC 11801 2010)	8946920000
 Mounting rail outlet, RJ45 module, IDC connection, IP20, Cat.6A / Class EA (ISO/IEC 11801 2010)	8808360000

RJ45 Patch Cords, LSZH, Shielded

Type	Order Number
 CabinetLine gray - length: 0.2 meter	1165940002
CabinetLine gray - length: 0.5 meter	1165940005
CabinetLine gray - length: 1 meter	1165940010
CabinetLine gray - length: 2.0 meter	1165940020
CabinetLine gray - length: 3.0 meter	1165940030
CabinetLine gray - length: 5.0 meter	1165940050
CabinetLine gray - length: 10 meter *	1165940100

* Available in custom lengths and over eight colors

Field Attachable RJ45 Connector

Type	Order Number
 RJ45 IP20 SteadyTec - EIA/TIA T568 A, EIA/TIA T568 B, PROFINET	1963600000
 RJ45 angled IP20 - EIA/TIA T568 B insulation cross-section: 1.1-1.6mm	1992890000
 RJ45 angled IP20 - EIA/TIA T568 B insulation cross-section: 0.85-1.1mm	1518090000
 RJ45 angled IP20 - EIA/TIA T568 A insulation cross-section: 0.85-1.1mm	1518080000
 RJ45 angled IP20 - EIA/TIA T568 A insulation cross-section: 1.1-1.6mm	1992870000

Panel Feed-through Adapter

Type	Order Number
 Adapter, straight, RJ45, M12, Cat.5 (ISO/IEC 11801), IP67	8901620000
 Adapter, angled, RJ45 90°, M12, Cat.5 (ISO/IEC 11801), IP67	8901630000

Service Ports FrontCom Micro

Type	Order Number
 FrontCom Micro RJ45 coupling	1018790000
 FrontCom Micro USB coupling, USB 2.0, type A	1018840000



Want to learn more about our connection solutions for your automation application?

Contact your local Weidmüller sales representative today at [weidmuller.com/sales](https://www.weidmuller.com/sales)

Weidmüller, Inc

821 Southlake Blvd.
Richmond, Virginia 23236
Telephone: (800) 849-9343
Website: www.weidmuller.com
Email: customerservice@weidmuller.com

Learn more:

[weidmuller.com/u-remote](https://www.weidmuller.com/u-remote)
[weidmuller.com/patchcables](https://www.weidmuller.com/patchcables)
[weidmuller.com/ethernetconnectors](https://www.weidmuller.com/ethernetconnectors)