


Integrated partition plate


| Dimensions                       |                    |
|----------------------------------|--------------------|
| Width / Height / Depth           | mm                 |
| Continuous operating temp., min. |                    |
| Continuous operating temp., max. |                    |
| Material                         |                    |
| UL 94 flammability rating        |                    |
| Ordering data                    |                    |
|                                  | dark beige         |
|                                  | matching terminals |
| Note                             |                    |

APP1

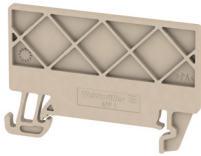


| 2.5 / 52.67 / 36.15 |      |            |
|---------------------|------|------------|
| -60 °C              |      |            |
| 130 °C              |      |            |
| Wemid               |      |            |
| V-0                 |      |            |
| Type                | Qty. | Order No.  |
| APP 1               | 50   | 2488970000 |
| A2C 1.5             |      | 1552790000 |
| A2C 1.5 PE          |      | 1552680000 |
| APGTB 1.5 FT 2C/1   |      | 2482160000 |
| APGTB 1.5 PE 2C/1   |      | 2482220000 |
| A2C 2.5             |      | 1521850000 |
| A2C 2.5 PE          |      | 1521680000 |
| APGTB 2.5 FT 2C/1   |      | 1513970000 |
| APGTB 2.5 PE 2C/1   |      | 1513870000 |
| Note                |      |            |

APP2

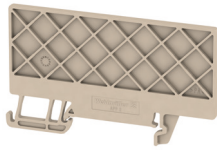

| 2.5 / 75.51 / 45.15  |      |            |
|----------------------|------|------------|
| -60 °C               |      |            |
| 130 °C               |      |            |
| Wemid                |      |            |
| V-0                  |      |            |
| Type                 | Qty. | Order No.  |
| APP 2                | 50   | 2489090000 |
| A3C 1.5              |      | 1552740000 |
| A3C 1.5 PE           |      | 1552670000 |
| A4C 1.5              |      | 1552690000 |
| A4C 1.5 PE           |      | 1552660000 |
| APGTB 1.5 FT 3C/1    |      | 2482180000 |
| APGTB 1.5 PE 3C/1    |      | 2482230000 |
| ADT 2.5 2C           |      | 1989800000 |
| A2C 2.5 /DT/FS       |      | 1989900000 |
| A2C 2.5 PE /DT/FS    |      | 1989890000 |
| A3C 2.5              |      | 1521740000 |
| A3C 2.5 PE           |      | 1521670000 |
| A4C 2.5              |      | 1521690000 |
| A4C 2.5 PE           |      | 1521540000 |
| APGTB 2.5 FT 3C/1    |      | 1514000000 |
| APGTB 2.5 PE 3C/1    |      | 1513890000 |
| AFS 2.5 CF 2C BK     |      | 2466530000 |
| AFS 2.5 CF 2C 12V BK |      | 2466610000 |
| AFS 2.5 CF 2C 24V BK |      | 2466600000 |
| A2C 4                |      | 2051180000 |
| A2C 4 PE             |      | 2051360000 |
| A3C 4                |      | 2051240000 |
| A3C 4 PE             |      | 2051410000 |
| A4C 4                |      | 2051500000 |
| A4C 4 PE             |      | 2051560000 |
| ADT 4 2C             |      | 2429850000 |
| AFS 4 2C BK          |      | 2429860000 |
| A2C 6                |      | 1992110000 |
| A2C 6 PE             |      | 1991810000 |
| Note                 |      |            |

APP3

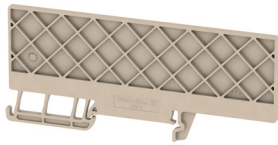


| 2.5 / 104.2 / 45.15 |      |            |
|---------------------|------|------------|
| -60 °C              |      |            |
| 130 °C              |      |            |
| Wemid               |      |            |
| V-0                 |      |            |
| Type                | Qty. | Order No.  |
| APP 3               | 50   | 2489100000 |
| APGTB 1.5 FT 4C/2   |      | 2482200000 |
| APGTB 1.5 PE 4C/2   |      | 2482240000 |
| APGTB 2.5 FT 4C/2   |      | 1514030000 |
| APGTB 2.5 PE 4C/2   |      | 1513920000 |
| ADT 2.5 3C          |      | 1989830000 |
| ADT 2.5 4C          |      | 1989860000 |
| A3C 6               |      | 1991820000 |
| A3C 6 PE            |      | 1991850000 |
| AAP11 ...           |      |            |
| AAP13 ...           |      |            |
| AI021 1.5 SI        |      | 1992260000 |
| AI021 1.5 SO        |      | 1992240000 |
| AI021 1.5 SO-PE     |      | 1992250000 |
| AI022 1.5 SI-PE     |      | 1992230000 |
| Note                |      |            |

Integrated partition plate

| Dimensions                       |                    |
|----------------------------------|--------------------|
| Width / Height / Depth           | mm                 |
| Continuous operating temp., min. |                    |
| Continuous operating temp., max. |                    |
| Material                         |                    |
| UL 94 flammability rating        |                    |
| Ordering data                    |                    |
|                                  | dark beige         |
|                                  | matching terminals |
| Note                             |                    |

APP4

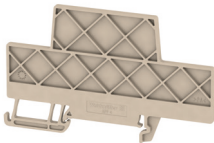

| 2.5 / 89.15 / 54.85  |      |            |
|----------------------|------|------------|
| -60 °C               |      |            |
| 130 °C               |      |            |
| Wemid                |      |            |
| V-0                  |      |            |
| Type                 | Qty. | Order No.  |
| APP 4                | 50   | 2489110000 |
| APGTB 1.5 2T 4C/2    |      | 2485840000 |
| APGTB 1.5 2T PE 4C/2 |      | 2485870000 |
| A2T 1.5              |      | 2469370000 |
| A2T 1.5 PE           |      | 2469410000 |
| A2T 2.5              |      | 1547610000 |
| A2T 2.5 PE           |      | 1547680000 |
| APGTB 2.5 2T 4C/2    |      | 1548060000 |
| APGTB 2.5 2T PE 4C/2 |      | 1548160000 |
| Note                 |      |            |

